


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010106](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect Crimp Contact Insert, Male, 42-Pole, 10A, for Turned Crimp Contacts, Size 10B «57x27»

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	10B «57X27»
Component Type	Inserts - Crimp Contact
Insert Series	S-DD
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
Taxonomy	Heavy-Duty Connectors
UPC	887191870748
Physical	
Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Male
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	48.000/g
Number of Rows	6
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	42
Temperature Range - Operating	-40° to +125°C
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	250V
Material Info	
Engineering Number	7142.4146.0

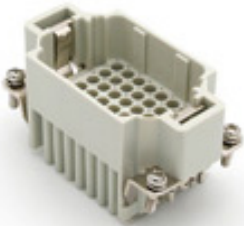

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2022)4187-DC (10 June 2022) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
Green Image Not Relevant Not Contained	

Search Parts in this Series
[93601](#) Series

Mates With
[936010105](#) Female Crimp Contact Insert

Use With
Turned Contacts - Male

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION