


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010113](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: GWconnect Crimp Contact Insert, Female, 72-Pole, 10A, Numbered 1-72, for Turned Crimp Contacts, Size 16B «77x27»

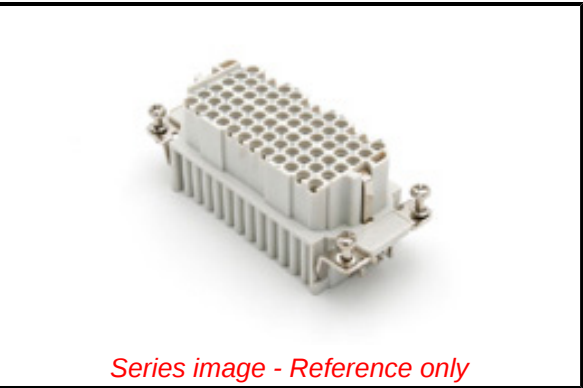

Series image - Reference only

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	16B «77X27»
Component Type	Inserts - Crimp Contact
Insert Series	S-DD
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
Taxonomy	Heavy-Duty Connectors
UPC	887191871318
Physical	
Durability (mating cycles max)	500
Flammability	UL 94V-0
Gender	Female
Insert Color	Grey
Material - Insert	Polycarbonate
Net Weight	58.000/g
Number of Rows	6
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	72
Temperature Range - Operating	-40° to +125°C
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	250V
Material Info	
Engineering Number	7172.4052.0

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[93601](#) Series

Mates With

[936010115](#) Male Crimp Contact Insert

Use With

Turned Contacts - Female

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION