

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010418](#)
Status: **Active**
Overview: GWconnect Heavy Duty Connectors (HDC)
Description: GWconnect Turned Crimp Contact for 40A Inserts and Modules, Male, Silver (Ag) Plated Copper Alloy, 2.50mm² (14 AWG), 100 per Bag

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification 936010406-S00 \(PDF\)](#)

Agency Certification

CSA 256883
 UL E249674

General

Product Family Industrial Connectors / Enclosures
 Series [93601](#)
 Contact Type Turned Crimp
 Overview [GWconnect Heavy Duty Connectors \(HDC\)](#)
 Product Category Contacts
 Product Name GWconnect
 Taxonomy Heavy-Duty Contacts
 UPC 887191889269

Physical

Gender Male
 Material - Contact Copper Alloy
 Material - Plating Silver
 Net Weight 3.020/g
 Number of Grooves 0
 Packaging Type Bag
 Stripping Length 9.00mm
 Wire Size AWG 14
 Wire Size mm² 2.50

Electrical


Current - Maximum per Contact 40.0A

Material Info

Engineering Number 7600.5711.0

Reference - Drawing Numbers

Product Specification 936010406-S00
 Sales Drawing 936010422-000

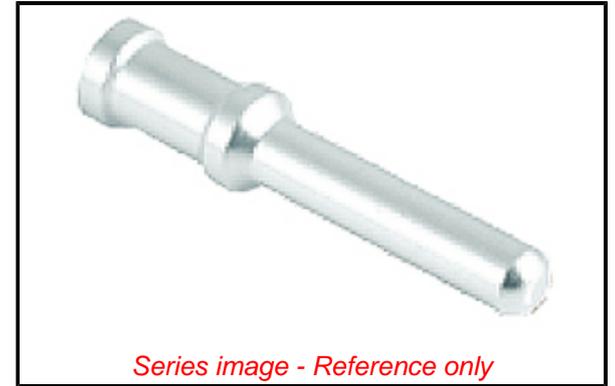

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per -
 D(2021)10043-DC (17
 Jan 2022)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

Green Image

Not Relevant

Not Contained

CER_4000400719_00_000.pdf

Search Parts in this Series

[93601 Series](#)

Mates With

[93601 Female Turned Crimp Contact](#)

Use With

S-K, S-Q, S-QD, and S-M Inserts