

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936011731

Status:

Active

Overview:


GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect STD - Standard, Double Lever Coupler, Die-cast Aluminum, with 2 Levers, Top Entry, with Gasket, Size 10B «57x27», Extended Pg16 Thread, Grey

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Component Size	10B «57X27»
Component Type	Double Lever Coupler
IP Rating	IP66
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Taxonomy	
Type	Heavy-Duty Connectors
UPC	STD 887191844961
Physical	
Entry Location	Top
Hood Coating	Polyester Powder
Hood Color	GREY RAL 7037
Lock to Mating Part	Yes
Material - Gasket	NBR
Material - Hood	Die-cast Aluminum
Material - Lever	Galvanized Steel
Net Weight	197.400/g
Number of Levers	2
Packaging Type	Bag
Thread Size	Pg16
Thread Type	(Pg)
Electrical	
Voltage - Maximum	500V
Material Info	
Engineering Number	7810.6536.0
Reference - Drawing Numbers	
Sales Drawing	936011774-000

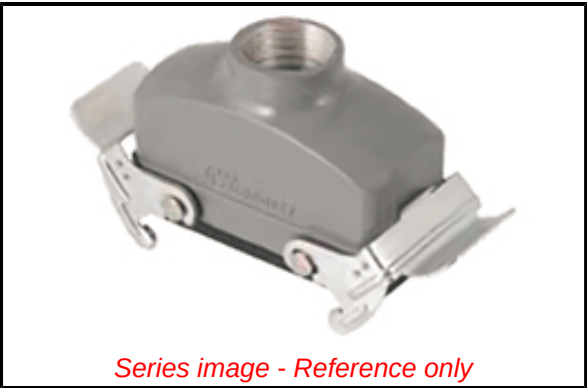

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE - Declaration of Conformity	CER_4000400719_00_000.pdf

Search Parts in this Series
93601 Series
Use With
Size 10B «57x27» S-D, S-DD, S-E, S-EE, S-EP, S-ES, S-HSB, S-ESHV, S-K, S-M, and S-EHV Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION