

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936040189](#)
Status: **Active**
Overview: [GWconnect Heavy Duty Connectors \(HDC\)](#)
Description: [GWconnect Enclosure, Die-cast Aluminum, S-8100 Series, without External Mounting Flanges, 50 x 45 x 30mm Outside Dimensions, Sandblasted](#)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Connectors / Enclosures
Series	93604
IP Rating	IP66, IP69
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Die-cast Enclosures
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 62208, NEMA ICS5, NEMA250, NMX-J235/1-2
Taxonomy	Die-cast Enclosures
Type	Sandblasted
UPC	887191878645

Physical


Internal Dimensions	44 x 39 x 25mm
Material - Enclosure	Die-cast Aluminum
Mounting Style	Internal Through Holes
Net Weight	85.000/g
Outside Dimensions	50 x 45 x 30mm
Packaging Type	Carton
Temperature Range - Operating	-40° to +125°C

Material Info

Engineering Number	8100.8205.0
--------------------	-------------

Reference - Drawing Numbers

Sales Drawing	936040083-000
---------------	---------------

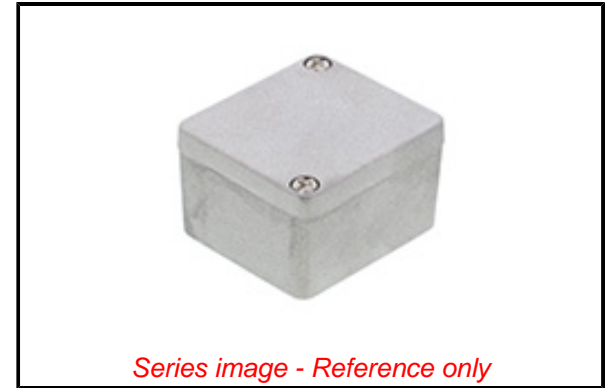

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[93604 Series](#)

Use With

DIN-rails, mounting supports, fixing screws, metal plates, and ground terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION