

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1120110022](#)  
**Status:** **Active**  
**Overview:** [PC Network Interface Cards](#)  
**Description:** SST PB3 Card, PROFIBUS DP Master/Slave, 1 and 2 Channel, PCI 3.3/ 5V -DLL/LIB - Control

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Network Interface
Series	<a href="#">112011</a>
Application	IO Control
Approvals	CE certified
Comments	2 channels
Overview	<a href="#">PC Network Interface Cards</a>
Product Name	SST
Protocol	PROFIBUS
Protocol Detail	PROFIBUS DPV0 Master, PROFIBUS DPV0 Slave, PROFIBUS DPV1 Master
Software Downloads	SST-PB3-PCU-2
Taxonomy	Network Interface Cards
Type	PROFIBUS Card
UPC	78678806109

**Physical**


Channels	2
Communication Speed	PROFIBUS 9.6 kbps to 12 Mbps
Interface	CommDTM, DLL, OPC DA
Mounting Style	PC Slot
Net Weight	140.000/g
Network Connection Type	PROFIBUS D-Sub Female (9 pin)
Operating System	Windows7, Windows8/8.1, Windows Server 2003, Windows Server 2008, Windows Server 2012, Windows Vista, WindowsXP
Packaging Type	Carton
Processor	ColdFIRE 5272
Slot	Universal PCI 3.3V/5V
Temperature Range - Operating	0°C to +60°C

**Electrical**

EMC	EN 61000-3-2, EN 61000-3-3, IEC 61000-6-2
Supply Voltage	3.3/5V

**Material Info**

Engineering Number	SST-PB3-PCU-2
--------------------	---------------

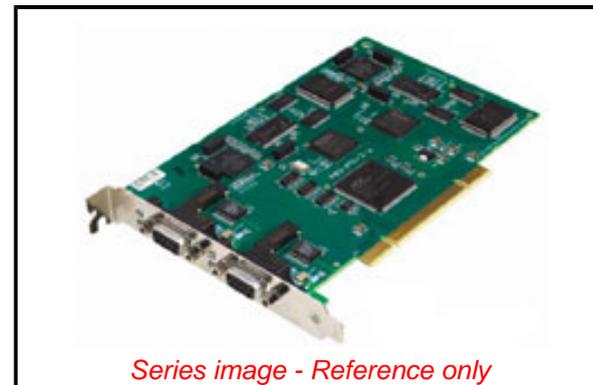

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[112011 Series](#)