

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200700175

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Receptacle, 4 Pole, 1/2" - 14 NPT Threads, Male (Straight) to 18 AWG Leads, 0.30m (11.81") Length

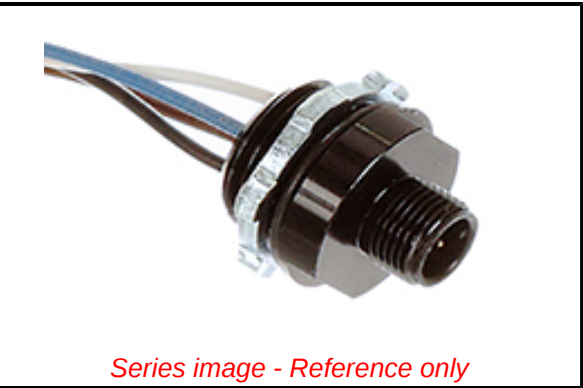

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	120070
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Taxonomy	Circular Industrial Connectors
Type	Single Ended (pigtail)
UPC	78678824302
Physical	
Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	0.30m
Material - Component	Black Anodized Aluminum
Mounting Thread Size	1/2" - 14 NPT
Net Weight	124.000/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	18
Wire/Cable Type	UL 1569
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	8R4006A16A120
Reference - Drawing Numbers	
Sales Drawing	SD-120070-044-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2022)4187-DC (10 June 2022)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE - Declaration of	CER_4000408918_00_000.pdf
Conformity	
ZZCERT_UKCA - Declaration of	CER_4000410285_00_000.pdf
Conformity	

Search Parts in this Series

120070 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION