

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200750015](#)
Status: **Active**
Overview: Brad Micro-Change (M12) Connectors
Description: Micro-Change (M12) Dual Keyway with PG9 Cable Fitting, Straight Female, 3 Poles, Cable Diameter 4.10-8.10mm

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	120075
Approvals	N/A
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (1/2" - 20 UNF)
Taxonomy	Circular Industrial Connectors
Type	Field Attachable Connector
UPC	78678830716

Physical

Cable Diameter	4.10-8.10mm (.161-.319")
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Dual
Material - Connector Body	PA
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Orientation	Straight
Poles	3
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	18

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC / 300V DC

Material Info

Engineering Number	7A3000-32
--------------------	-----------

Reference - Drawing Numbers

Sales Drawing	SD-120075-007-001
---------------	-------------------

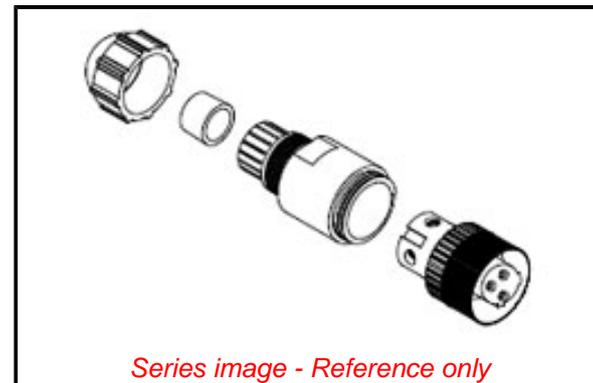

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[120075 Series](#)