

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200998001](#)
Status: **Active**
Overview: PROFIBUS Solutions
Description: PROFIBUS Receptacle, 5 Poles, Male (Straight) to Lead, 3.0m (9.84') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	120099
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	PROFIBUS Solutions
Product Name	PROFIBUS Data Line
Taxonomy	Circular Industrial Connectors
Type	Single Ended (pigtail)
UPC	883906347956

Physical

Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	3.0m
Material - Component	Nickel-plated Brass
Mounting Thread Size	M16
Orientation	Back Panel Mount to Straight
Panel Mount	Back
Poles	5
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	N/A

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V

Material Info

Engineering Number	BR5U76PP4M0303
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-120099-001-001
---------------	-------------------

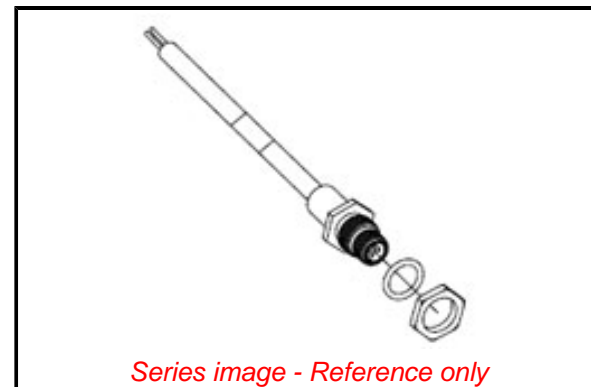

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_UKCA

- Declaration of

Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000406115_00_000.pdf

Search Parts in this Series

[120099 Series](#)

Mates With

[120099 Female](#)