

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201030005](#)
Status: **Active**
Overview: [profibus solutions](#)
Description: D-Sub Connector without Diagnostics LEDs, 90° Angle

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	120103
IP Rating	IP67
Overview	profibus solutions
Product Name	Profibus*
Type	Field Attachable Connector

Physical

Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	Yes
Diagnostics Port	No
Gender	N/A
Keyway	None
Material - Connector Body	Die-Cast Zinc
Material - Contact	N/A
Material - Coupling Nut	N/A
Material - Plating Mating	n/a
Orientation	90° Angle
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	4A
Voltage - Maximum	30V

Material Info

Old Part Number	PA9S01-42
-----------------	-----------

Reference - Drawing Numbers

Sales Drawing	SD-120103-004
---------------	---------------

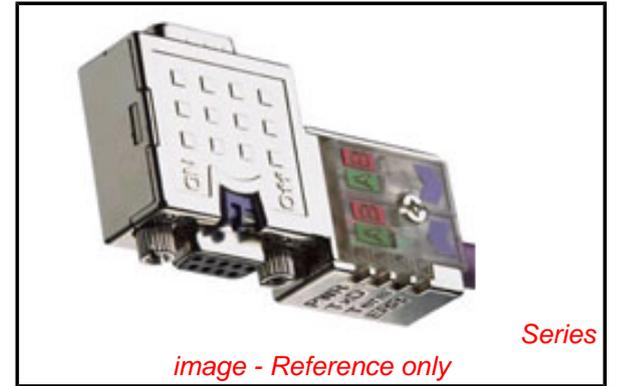

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[120103Series](#)