

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201088166

Status:

Active

Overview:


Brad Industrial Ethernet Solutions

Description:

Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 24 AWG, Blue Unshielded TPE Cable, 1.0m (3.28') Length, 6.99mm (.275") Diameter

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Cordsets
Series	120108
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP20
Material - Contact	Phosphor Bronze
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet
Protocol	EtherNet
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	78172539873
Physical	
Cable Diameter	6.99mm (.275")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Blue
Coupling Style	N/A
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	Polycarbonate
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	122.000/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +75°C
Wire Size AWG	24
Wire/Cable Type	Unshielded TPE
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	30V AC / 60V DC
Material Info	
Engineering Number	E66A06006M010
Reference - Drawing Numbers	
Sales Drawing	SD-120108-054-001

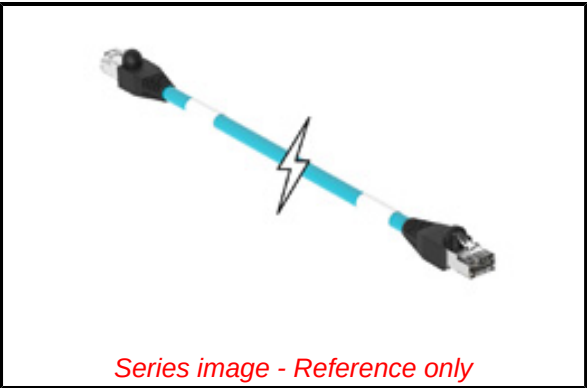

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Contained Per -	
D(2022)4187-DC (10	
June 2022)	
Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE -	CER_4000410038_00_000.pdf
Declaration of	
Conformity	
ZZCERT_UKCA	CER_4000410298_00_000.pdf
- Declaration of	
Conformity	

Search Parts in this Series

120108 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION