

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201088339](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male RJ-45 (Straight), 22 AWG, Green Shielded TPU Cat5e Cable, 15.0m (49.21') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120108
Connector End A	Micro-Change (M12)
Connector End B	RJ-45 (standard)
IP Rating	IP20, IP67
Material - Contact	Brass, Phosphor Bronze
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Micro-Change (M12), RJ45
Region	Asia
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	889056150842

Physical

Cable Diameter	6.80mm (.268")
Cable Length	15.0m (49.21')
Color - Cable Jacket	Green
Coupling Style	Push and Latch, Threaded
Gender	Male-Male
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	TPU
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	1105.000/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-40° to +80°C
Wire Size AWG	22
Wire/Cable Type	Shielded TPU

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info

Engineering Number	E16A06012M150
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	1201080521-000
---------------	----------------

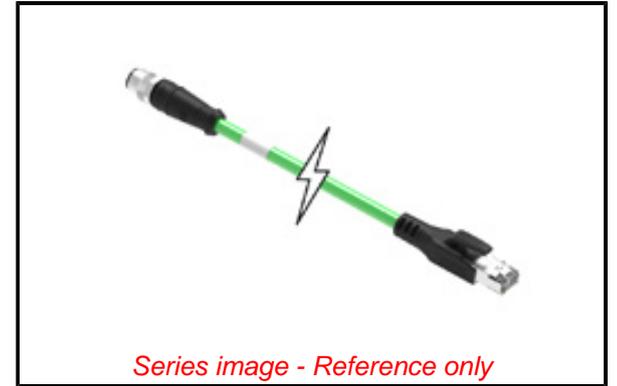

EU ELV

Not Reviewed

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Reviewed

RoHS Phthalates

Not Contained

ZZCERT_CE -

CER_4000410038_00_000.pdf

Declaration of

Conformity

ZZCERT_UKCA

CER_4000406014_00_000.pdf

- Declaration of

Conformity

Search Parts in this Series

[120108 Series](#)