

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201088340](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male RJ-45 (Straight), 22 AWG, Green Shielded TPU Cat5e Cable, 20.0m (65.62') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120108
Connector End A	Micro-Change (M12)
Connector End B	RJ-45 (standard)
IP Rating	IP20, IP67
Material - Contact	Brass, Phosphor Bronze
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Micro-Change (M12), RJ45
Region	Asia
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	889056150859

Physical

Cable Diameter	6.80mm (.268")
Cable Length	20.0m (65.62')
Color - Cable Jacket	Green
Coupling Style	Push and Latch, Threaded
Gender	Male-Male
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	TPU
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	1430.000/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-40° to +80°C
Wire Size AWG	22
Wire/Cable Type	Shielded TPU

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info

Engineering Number	E16A06012M200
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	1201080521-000
---------------	----------------

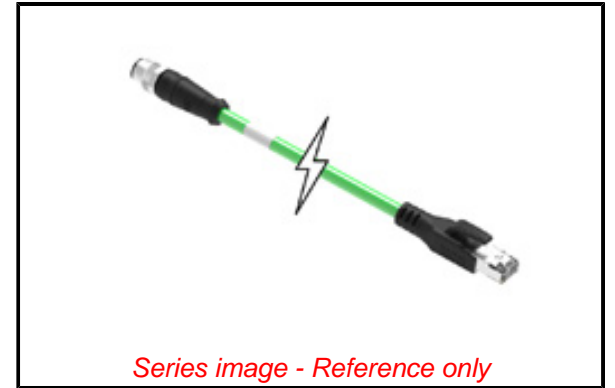

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[120108 Series](#)