

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1201088474

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 24 AWG, Teal Shielded TPU Cable, 1.0m (3.28') Length, 6.50mm (.256") Diameter

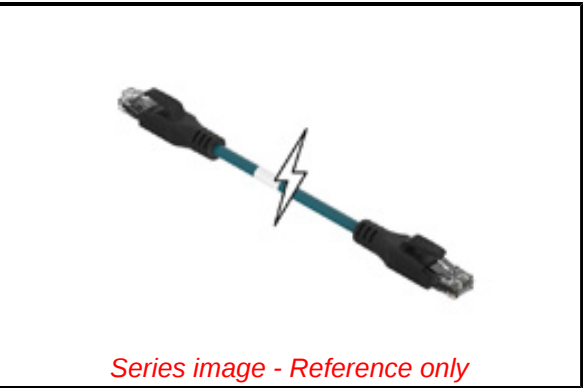

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Cordsets
Series	120108
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP20
Material - Contact	Phosphor Bronze
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	889056361156
Physical	
Cable Diameter	6.50mm (.256")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Teal
Coupling Style	Push and Latch
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	TPU
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	26.988/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +50°C
Wire Size AWG	24
Wire/Cable Type	Shielded TPU
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V
Material Info	
Engineering Number	E66A06016M010
Reference - Drawing Numbers	
Sales Drawing	1201088967-000, SD-120108-081-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_UKCA	CER_4000410298_00_000.pdf
- Declaration of Conformity	

Search Parts in this Series

120108 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION