

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210120019](#)
Status: **Active**
Overview: [mPm DIN Valve Connectors](#)
Description: mPm DIN Base, Form A-18mm, B20 Base, 3 Pole Plus Ground Terminal, 250V AC/300V DC, Black, Nitrile Gasket with Screw

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-121012-B20-001 \(PDF\)](#)
[Product Specification STR-1467-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Field Attachable / Accessories
Series [121012](#)
Form A - 18mm
IP Rating IP65, IP67
Material - Contact Brass
Overview [mPm DIN Valve Connectors](#)
Product Name mPm
Taxonomy Circular Industrial Connectors
Type Field Attachable Connector
UPC 883906278069

Physical

Cable Diameter N/A
Coupling Type N/A
Diagnostics / LEDs No
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polypropylene
Material - Coupling Nut N/A
Material - Plating Mating Silver
Net Weight 9.979/g
Orientation Straight
Pitch - Mating Interface 18.00mm
Poles 3
Temperature Range - Operating -40°C to +90°C
Wire Size AWG N/A

Electrical


Current - Maximum per Contact 16.0A
Voltage - Maximum 250V AC / 300V DC

Material Info

Engineering Number B203000N2

Reference - Drawing Numbers

Packaging Specification PK-121012-B20-001
Product Specification STR-1467-001
Sales Drawing SD-121012-013-001

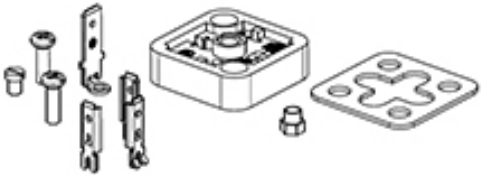

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
D(2022)4187-DC (10
June 2022)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[121012](#) Series