

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1210230434](#)  
**Status:** **Active**  
**Overview:** mPm DIN Valve Connectors  
**Description:** mPm DIN Valve Connector, Form C-Micro 9.4mm, PG7 Internal Threads, 2 Pole Plus Ground Terminal, 250V AC/300V DC, Black, Nitrile Gasket and Screw, Bulk Pack Mounted

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Packaging Specification PK-121023-C19-001 \(PDF\)](#)

**Agency Certification**

UL E218123

**General**

Product Family Field Attachable / Accessories  
 Series [121023](#)  
 Form C - Micro 9.4mm  
 IP Rating IP65, IP67  
 Material - Contact Brass  
 Overview [mPm DIN Valve Connectors](#)  
 Product Name mPm  
 Taxonomy Circular Industrial Connectors  
 Type Field Attachable Connector  
 UPC 883906249045

**Physical**

Cable Diameter N/A  
 Coupling Type Internal Thread  
 Diagnostics / LEDs No  
 Diagnostics Port No  
 Gender N/A  
 Keyway None  
 Material - Connector Body Polypropylene  
 Material - Coupling Nut N/A  
 Material - Plating Mating Silver  
 Orientation 90° Angle  
 Pitch - Mating Interface 9.40mm  
 Poles 2  
 Temperature Range - Operating -40°C to +90°C  
 Wire Size AWG N/A

**Electrical**


Current - Maximum per Contact 16.0A  
 Voltage - Maximum 250V AC / 300V DC

**Material Info**

Engineering Number C19207N22

**Reference - Drawing Numbers**

Packaging Specification PK-121023-C19-001  
 Sales Drawing SD-121023-005-001

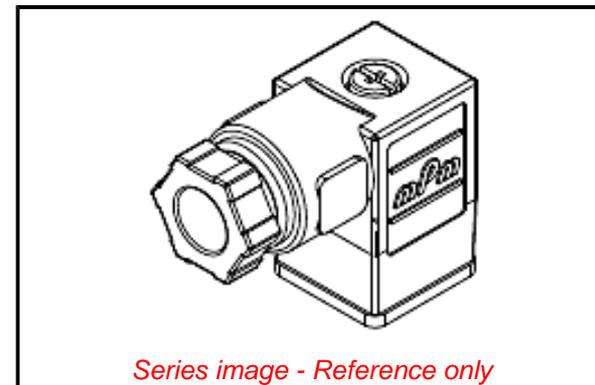

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

[121023 Series](#)