

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210360195](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: Micro-Change (M12) to Brad mPm DIN Form A - 18mm Cordset, 5 Poles, Male (90°), 2.0m (6.56') Length, 24V

Documents:
[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Industrial Cordsets
Series [121036](#)
Connector End A Brad mPm DIN A - 18mm
Connector End B Micro-Change (M12)
IP Rating IP65
Material - Contact Copper Alloy
Overview [mPm DIN Valve Connectors](#)
Product Name Micro-Change (M12), mPm
Protocol N/A
Region America, Europe
Taxonomy Circular Industrial Cordsets
Type Double Ended
UPC 883906334796

Physical
Cable Diameter 5.72mm (.225")
Cable Length 2.0m (6.56')
Color - Cable Jacket Black
Coupling Style Threaded
Gender Male-Male
Keyway Single
LED Indicator No
Material - Cable Jacket PUR
Material - Connector Body Polypropylene
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating Gold
Net Weight 89.846/g
Orientation 90° to Straight
Poles 5
Temperature Range - Operating -25° to +75°C
Wire Size AWG 22
Wire/Cable Type Shielded PUR

Electrical
Current - Maximum per Contact 1.5A
Voltage - Maximum 24V

Material Info
Engineering Number E850B0P12M020

Reference - Drawing Numbers
Sales Drawing SD-121036-001-001

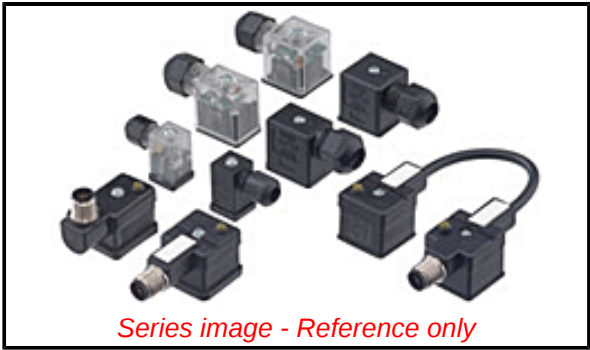

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Reviewed	
Halogen-Free Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[121036](#) Series