

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130039-0230](#)
Status: **Active**
Overview: Brad® Micro-Change® (M12) Connectors
Description: Micro-Change® (M12) Double-Ended Cordset, 5 Poles, Male (Straight) to Female (Straight), DeviceNet* Standard Cable, 0.50m (1.64') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series [130039](#)
 Connector End A Micro-Change® (M12)
 Connector End B Micro-Change® (M12)
 IP Rating IP67
 Overview [Brad® Micro-Change® \(M12\) Connectors](#)
 Product Name DeviceNet*, Micro-Change® (M12)
 Protocol DeviceNet*
 Region Europe
 Type Double Ended
 UPC 78678882411

Physical

Cable Diameter N/A
 Cable Length 0.50m (1.64')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Male-Female
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Contact Brass
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold
 Net Weight 5.210/g
 Orientation Straight
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 22
 Wire/Cable Type E152210

Electrical

Current - Maximum per Contact 4A
 Voltage - Maximum 250V AC


Material Info

Old Part Number DNDC302A-M005

Reference - Drawing Numbers

Sales Drawing SD-130039-028

*DeviceNet is a trademark of the ODVA

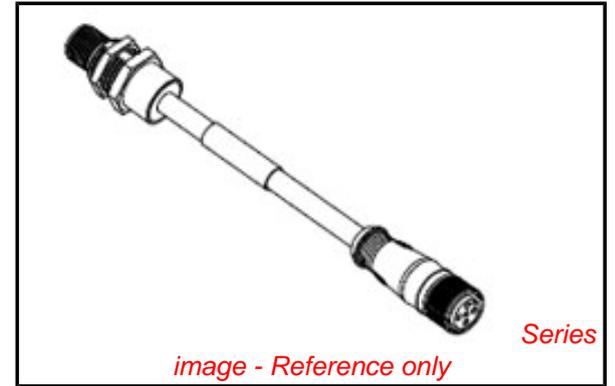

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Not Reviewed**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130039Series

This document was generated on 10/02/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION