

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300480062](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Micro-Change (M12) Single-Ended Cordset, 4 Poles, Male (90°) to Pigtail, 24 AWG PVC Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E200650

General

Product Family	Industrial Cordsets
Series	130048
Connector End A	Micro-Change (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Micro-Change (M12)
Protocol	N/A
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Single Ended
UPC	78678803920

Physical

Cable Diameter	5.59mm (.220")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Teal
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Orientation	90° to Pigtail
Poles	4
Temperature Range - Operating	-20° to +75°C
Wire Size AWG	24
Wire/Cable Type	N/A

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info

Engineering Number E10A00703M010

Reference - Drawing Numbers

Sales Drawing SD-120108-016-001

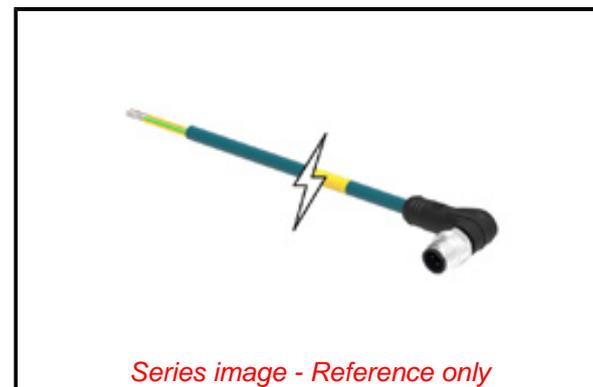

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per - ED/108/2014 (17 Dec 2014)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_UKCA

- Declaration of

Conformity

50 Image

Not Relevant

Not Contained

CER_4000410546_00_000.pdf

Search Parts in this Series

130048 Series

This document was generated on 09/01/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION