

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300570001](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Brad RJ-Lnxx, Threaded, RJ-45 Ethernet Field-Attachable Connector for Stranded Core Cable

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Field Attachable / Accessories
Series	130057
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Product Name	Brad, RJ-Lnxx
Type	Field Attachable Connector
UPC	78678848445

Physical

Cable Diameter	N/A
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	None
Material - Connector Body	Polycarbonate
Material - Coupling Nut	ABS
Material - Plating Mating	n/a
Net Weight	22.960/g
Orientation	Straight
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V

Material Info

Engineering Number	ENQAM315
--------------------	----------

Reference - Drawing Numbers

Sales Drawing	SD-130057-001
---------------	---------------

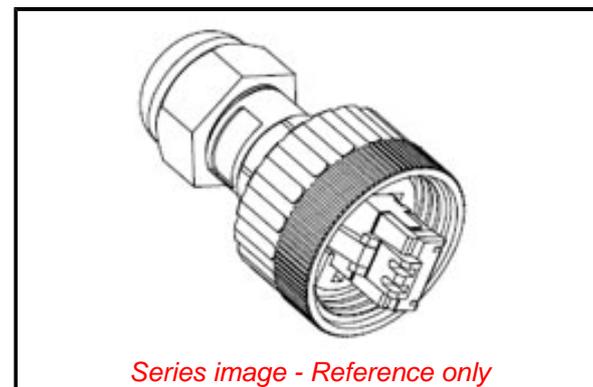

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130057](#) Series