

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300660235](#)
Status: **Active**
Overview: BradPower Cordsets and Receptacles
Description: BradPower D-Size (1 3/8"-M35) Receptacle, 1/2" - 14 NPT, 4 Poles, Female (Straight) to 10 AWG Leads, 0.5m (19.7") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Receptacles
 Series [130066](#)
 IP Rating IP67
 Overview [BradPower Cordsets and Receptacles](#)
 Product Name BradPower D-Size
 Taxonomy Circular Industrial Connectors
 Type Single Ended (pigtail)
 UPC 78172501820

Physical

Coupling Type Internal Thread
 Gender Female
 Keyway Single
 Length 0.50m
 Material - Component Clear Anodized Aluminum
 Mounting Thread Size 1/2" - 14 NPT
 Net Weight 234.053/g
 Orientation Straight
 Panel Mount Front
 Poles 4
 Temperature Range - Operating -20° to +105°C
 Wire Size AWG 10
 Wire/Cable Type UL 1015

Electrical

Current - Maximum per Contact 32.0A
 Voltage - Maximum 600V

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number CR4000A76M005

Reference - Drawing Numbers

Sales Drawing SD-130066-005-001

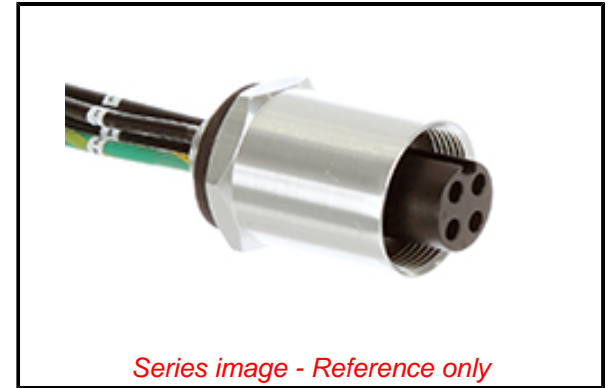

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

ZZCERT_UKCA

- Declaration of

Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000406200_00_000.pdf

CER_4000410292_00_000.pdf

Search Parts in this Series

[130066 Series](#)