

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300900010](#)  
**Status:** **Active**  
**Overview:** [Reels - Woodhead](#)  
**Description:** Woodhead Standard Duty Reel, 16/3 SJTOW Cord, 10.67m (35.0') Cord Length with 13W Fluorescent Hand Lamp and Handle Ballast

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E22769

**General**

Product Family Electric Reels  
 Series [130090](#)  
 Cable Length 0.457m (1.50')  
 Comments Ratchet Lock (ON/OFF Switchable)  
 Depth 0.24m (9.59")  
 Duty Standard  
 Enclosure Rating NEMA 1  
 Height 0.32 (12.62")  
 NEMA Configuration NEMA 5-15  
 Overview [Reels - Woodhead](#)  
 Product Name Super-Safeway  
 Taxonomy Electric Reels  
 Type Cord Reel  
 UPC 78678827906  
 Width 13.06mm (5.160")

**Physical**

Cable Movement Ratchet Lock  
 Cord Length 10.67m (35.0')  
 Drum Lock Ratchet  
 Material - Coating Powder Coating  
 Material - Housing Steel  
 Mounting Style Swinging  
 Number of Conductors 3  
 Packaging Type Carton  
 Primary Cord/Cable Entry N/A  
 Retraction Weight 0.9kg (2.0 lb)  
 Wire Size AWG 16

**Electrical**


Bulb Included Yes  
 Cord Type 16/3 SJTOW  
 Current - Maximum per Contact 6.0A  
 GFCI No  
 Lamp Type Fluorescent  
 Lamp Wattage - Maximum 13W  
 On/Off Switch Yes  
 Voltage - Maximum 120V

**Material Info**

Engineering Number 945-3-86

**Reference - Drawing Numbers**

Sales Drawing 3300T

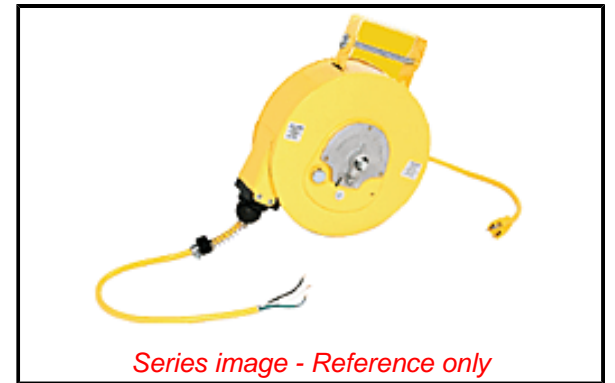

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130090](#) Series

This document was generated on 10/13/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**