

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300920109](#)  
**Status:** **Active**  
**Overview:** [Slip Rings](#)  
**Description:** Aero-Motive Slip Ring Component Kit, 30A, 12 AWG, 4 Conductors, Bore Size 22.23mm (.875") Diameter

**Documents:**


[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Slip Rings
Series	<a href="#">130092</a>
Center Bore Diameter	22.23mm (.875")
Component Type	Component Kit
Current - Maximum per Contact	30.0A
Mounting Style	Horizontal, Vertical
Number of Conductors	4
Overview	<a href="#">Slip Rings</a>
Packaging Type	Carton
Product Name	Aero-Motive
Speed (RPM)	Continuous 125
Taxonomy	Slip Rings
Temperature Range - Operating	-40°C to +120°C
UPC	78678859312
Voltage - Maximum	600V
Wire Size AWG	12

**Material Info**

Engineering Number SR24

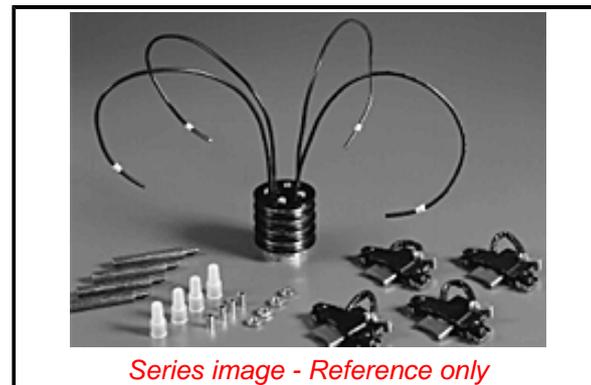

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130092](#) Series

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**