

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940530](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 3", Cable Diameter 5.84-8.13mm (.230-.320"), Approximate Break Strength 136.08kg (300 lbs)

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

| | |
|----------------|-------------------------------|
| Product Family | Cable Grips |
| Series | 130094 |
| Eye Type | Single |
| O-Ring | N/A |
| Overview | Support Grips |
| Product Name | Fiber Optic |
| Taxonomy | Cable Grips |
| Type | Support Grip |
| UPC | 78678836681 |

Physical


| | |
|----------------------------|------------------------------|
| Approximate Break Strength | 136.08kg (300 lbs) |
| Bale Length | 0.076m (3.00") |
| Body Style | Straight |
| Cable Diameter | 5.84-8.13mm (.230-.320") |
| Color - Grommet | Orange |
| Gender | N/A |
| Material - Body | N/A |
| Material - Grip | Non-magnetic Tin Bronze Wire |
| Mesh Length | 0.064m (2.50") |
| Number of Holes | N/A |
| Thread Size | N/A |

Material Info

Engineering Number 36681

Reference - Drawing Numbers

Sales Drawing SD-130094-008-001

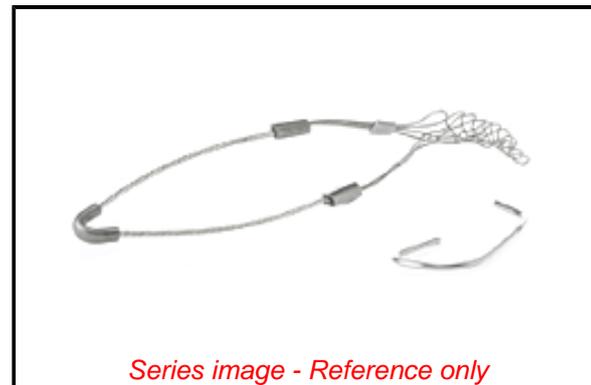

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)