

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300980195

Status:


Active

Overview:

Strain-Relief Cord Grips

Description:

MAX-LOC Multi-Hole Strain Relief, 1/2" NPT, Straight Male, Cable Diameter 5.72mm (.225")

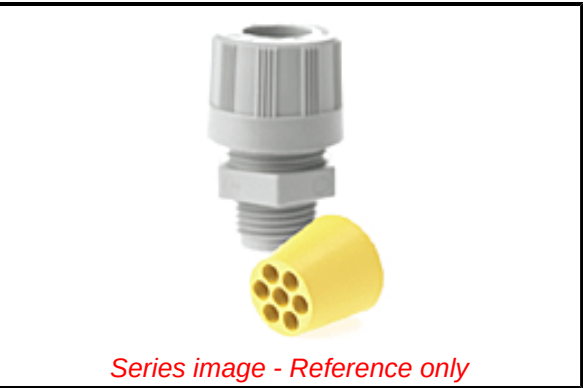

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Brochure \(PDF\)](#)

Agency Certification	
CSA	LR32159
UL	E76954
General	
Product Family	Cable Grips
Series	130098
Comments	Indicates that one or more grommet hole is covered by a thin membrane which can easily be "Poked" open if required.
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	Strain-Relief Cord Grips
Product Name	MAX-LOC
Taxonomy	Cable Grips
Type	Strain Relief Grip
UPC	78678850409
Use With	1/2" NPT MAX-LOC Lock Nut 1300990143 , MAX-LOC O-Ring, 1/2" NPT 1301800314 , 1/2" NPT MAX-LOC Gasket 1300990149
Physical	
Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	5.72mm (.225")
Color - Grommet	Yellow
Gender	Male
Material - Body	Nylon
Material - Grip	N/A
Mesh Length	N/A
Number of Holes	2, 3, or 4
Thread Size	1/2" NPT
Material Info	
Engineering Number	5594-004
Reference - Drawing Numbers	
Sales Drawing	SD-130098-195-001

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

130098 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION