

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130108-0092](#)
Status: **Active**
Description: Super-Safeway™ 8W Fluorescent Hand Lamp with Cord Ballast Location and no Switch, Cord Type 18/3 SJTW, Cord Length 5.49m (18.0')

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR85374

General

Product Family	Portable Lighting
Series	130108
Depth	31.75mm (1.250")
Height	N/A
Length	495.30mm (19.500")
NEMA Configuration	NEMA 5-15
Outlet	None
Product Name	Super-Safeway™
Type	Hand Lamps
Woodhead	Yes

Physical


Cord Length - Primary	5.49m (18.0')
Cord Length - Secondary	N/A
Duty	Industrial
Guard Included	No
Guard Type	N/A
Material - Globe	Butyrate
Material - Guard	Nitrile Rubber 80 Shore A
Mounting Style	Hand Held
Packaging Type	Carton
Socket Construction	N/A

Electrical

Bulb Type	Fluorescent
Cord Type - Primary	18/3 SJTW
Lamp Type	F8/T5
Lamp Wattage - Maximum	8W
Lumens	300
On/Off Switch	No
Voltage (Fixture) - Maximum	120VAC 60 HZ

Material Info

Old Part Number	1049
UPC	78678861235

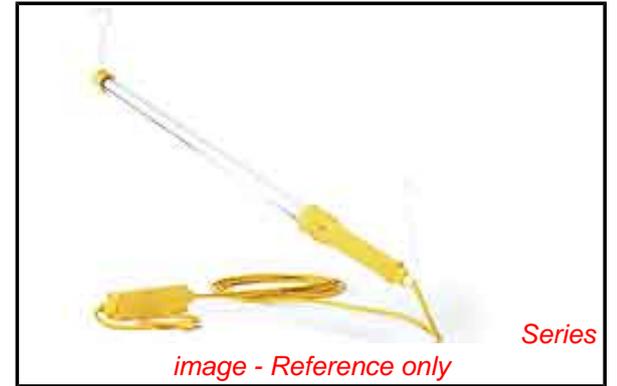

EU RoHS Not RoHS Compliant REACH SVHC Not Reviewed Low-Halogen Status Not Reviewed	China RoHS 
--	--

Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[130108Series](#)