


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460156](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Receptacle with Single Flip Coverplate, 2 Pole/2 Wire, NEMA-L2-20, 250V

Documents:

3D Model (PDF)	Brochure (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model	

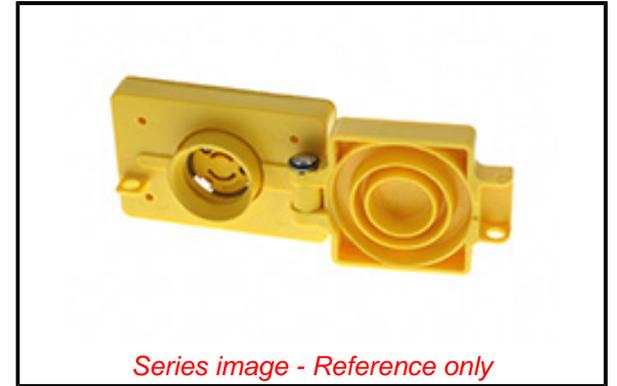

Agency Certification

CSA	LR6837
UL	E68122

General

Product Family	Wiring Devices
Series	130146
IP Rating	IP67
NEMA Configuration	NEMA L2-20
Overview	Watertite Extreme Wet-Location Wiring Solutions
Product Name	Watertite Extreme
Receptacle Type	Single
Specialty	N/A
Taxonomy	Wiring Devices
Type	Receptacle
UPC	78678871458

Physical

Flange	No
Flip Lid	No
Gender	Female
Length	N/A
Locking Blade	Yes
Poles	2-pole/2-wire

Electrical

Cord Type	N/A
Current - Maximum per Contact	20.0A
GFCI	No
Lighted Connector	No
Voltage - Maximum	250V

Material Info

Engineering Number	67W07
--------------------	-------

Reference - Drawing Numbers

Sales Drawing	1301460156-000
---------------	----------------

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Relevant

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

[130146 Series](#)