

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1302430021](#)
Status: **Active**
Overview: Wide-Area Lighting Products
Description: Haztex Wide Area LED Work Light, 4 x 20W, Plug 14/3 SOOW 7.62m (25.0')

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|--------------------|--|
| Product Family | Portable Lighting |
| Series | 130243 |
| Comments | Class 1, Division 2, Groups B, C, and D, Class 1, Division 2, Groups B, C, and D |
| NEMA Configuration | NEMA 5-15 |
| NEMA Rating | NEMA 3R |
| Outlet | None |
| Overview | <u>Wide-Area Lighting Products</u> |
| Product Name | Haztex |
| Type | Wide Area Lamps |
| UPC | 78172536905 |

Physical


| | |
|-------------------------|---------------------|
| Cord Length - Primary | 7.62m (25.0') |
| Cord Length - Secondary | N/A |
| Depth | 176.90m (6.960") |
| Duty | Hazardous |
| Guard Included | No |
| Guard Type | N/A |
| Height | 166.50mm (6.555") |
| Length | 706.37mm (27.810") |
| Material - Globe | Clear Polycarbonate |
| Material - Guard | Silicone Rubber |
| Mounting Style | Variable |
| Packaging Type | Carton |
| Socket Construction | N/A |

Electrical

| | |
|-----------------------------|------------|
| Bulb Type | LED |
| Cord Type - Primary | 14/3 SOOW |
| Lamp Type | 20W LED |
| Lamp Wattage - Maximum | 20W x 4 |
| Lumens | 5270 |
| On/Off Switch | No |
| Voltage (Fixture) - Maximum | 120V, 277V |

Material Info

| | |
|--------------------|----------------|
| Engineering Number | 1076HZ25025143 |
|--------------------|----------------|

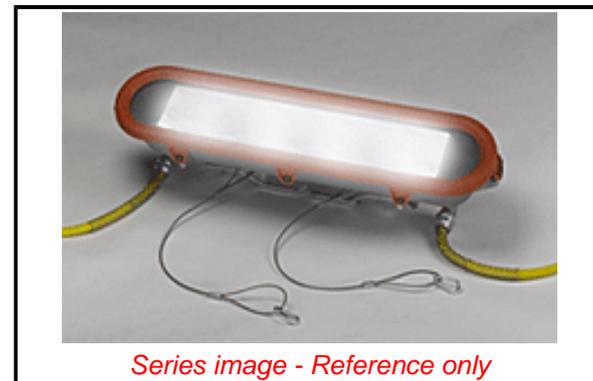

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130243](#) Series