


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2004880006](#)
Status: **Active**
Overview: [Mini-Fit Family Power Connectors](#)
Description: Mini-Fit TPA2 Plug Housing, 4.20mm Pitch, Single Row, UL 94V-0, Low-Halogen, Panel Mount, 6 Circuits

Documents:
[Drawing \(PDF\)](#) [Application Specification AS-172718-0000-001 \(PDF\)](#)
[3D Model](#) [Packaging Specification 2004880000-PK-000 \(PDF\)](#)
[3D Model \(PDF\)](#) [Test Summary 1727180002-TS-000 \(PDF\)](#)
[Product Specification PS-172718-0000-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	EU-01109
General	
Product Family	Crimp Housings
Series	200488
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	See product specification for current derating information.
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit TPA2
Taxonomy	Connector Housings
UPC	889056436465
Physical	
Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2.680/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info	
Reference - Drawing Numbers	
Application Specification	AS-172718-0000-001
Packaging Specification	2004880000-PK-000
Product Specification	PS-172718-0000-001
Sales Drawing	2004880000-SD-000
Test Summary	1727180002-TS-000

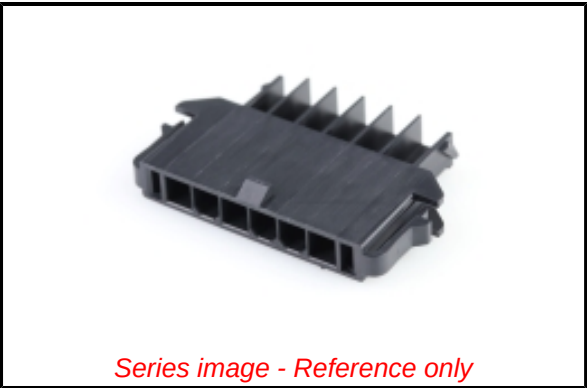

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - Halogen-Free Status Low-Halogen	China RoHS
For more information, please visit Contact US	
China ROHS ELV RoHS Phthalates	Green Image Not Relevant Not Contained

Search Parts in this Series
[200488](#) Series

Mates With
Mini-Fit TPA2 Receptacle Housing [200453](#)

Mini-Fit Jr. Receptacle Housing [5557](#)

Mini-Fit TPA2 Cable Assembly [145135](#)

Use With
Mini-Fit TPA2 Male Terminal [172765](#)

Mini-Fit TPA2 Retainer [172709](#)