



What can we help you find?




- Products
- Industries
- Resources
- About TE
- My Account
- Innovation
- Support Center

Home > Products > Tubing & Harnessing > Product Feature Selector > Product Details

222D152-3-00-0 Product Details

Share Print Email

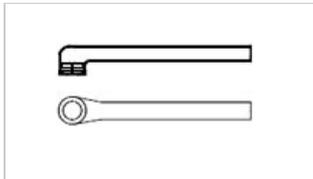

Active

Molded Parts

222D152-3-00-0

222D152-3-00-0

TE Internal Number: 807206-000

Product Highlights [View All](#)

- SAE AS81765/1 Type I
- Molded Part Type = Molded Boot
- Molded Part Shape = 90°
- Molded Part Lip = With Lip
- Operating Temperature = -55 - 135 °C

- Pricing & Availability
- Request Sample
- Add to My Part List
- Buy Product through Distributor

- Documents
- Features
- Compliance

Please Note:

Use the Product Drawing for all design activity

Product Type Features		Configuration Features	
Molded Part Type	Molded Boot	Material Code	3
Molded Part Shape	90°	Industry Standards	
Molded Part Lip	With Lip	Government/Industry Qualification	No
Angle	90°	Approved Standards	SAE AS81765/1 Type I
Adhesive Description	Adhesive Purchased Separately	RoHS/ELV Compliance	RoHS compliant, ELV compliant
Size	52	Lead Free Solder Processes	Not relevant for lead free process
Family Name	222D1	RoHS/ELV Compliance History	Always was RoHS compliant
Color	Black	Environmental	
Mechanical Attachment		Operating Temperature (°C)	-55 - +135
Adhesive Pre-Coating	Without	Operation/Application	
Dimensions		Application	General Purpose
Cable Diameter Range (mm [in])	22.40 - 36.00 [0.880 - 1.420]	Purchasing Information	
Expanded ID, Min. (mm [in])	36.00 [1.420]	Adhesive Code	S1017, S1048
Recovered ID, Max. (mm [in])	22.40 [0.880]	Other	
Body Features		Brand	Raychem
Wall Thickness - Full Recovery (Nominal) (mm [in])	1.80 [0.071]		
Material	Semi rigid Modified Polyolefin		
Housing Features			
Material Systems Code	10		
Max. Inside Diameter of Part (mm [in])	22.40 [0.880]		

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Feedback

[About TE](#)

[Investors](#)

[News Room](#)

[Supplier Portal](#)

[Careers](#)

[Terms & Conditions](#)

[Privacy Policy](#)

[Global Accessibility Statement](#)

[Distributor Inventory](#)

[Product Cross Reference](#)

[Documents & Drawings](#)

[Product Compliance Support Center](#)

[Site Map](#)

[Email or Chat With Us](#)

[Find a Phone Number](#)

[Knowledge Base](#)

[Manage Your Account](#)

