


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190690241](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite™ Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 3/8" (M9), Length 26.82mm

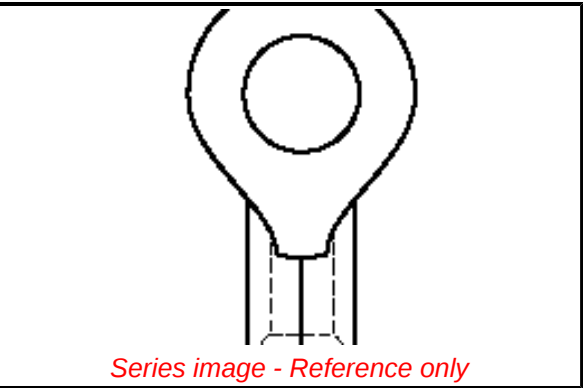

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19069
Crimp Quality Equipment	Yes
Mil-Spec	N/A
MolexKits	Yes
Overview	Solderless Terminals
Product Name	Krimptite™
Type	Ring
UPC	800755067545

Physical	
Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.996/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	3/8" (M9)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	10, 12
Wire Size mm²	4.00-6.00

Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	C-140-38

Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	CCD10101

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/30/2017 (7 July 2017) Halogen-Free Status Low-Halogen	China RoHS
---	-------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19069](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION