

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191930179](#)
Status: **Active**
Overview: [VersaKrimp™ Terminals and Splices](#)
Description: [VersaKrimp™ Ring Tongue Terminal for 8 AWG Wire](#)

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series [19193](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [VersaKrimp™ Terminals and Splices](#)
Product Name VersaKrimp™
Type Ring
UPC 800755050288

Physical
Barrel Type Closed - Brazed
Insulation None
Material - Plating Mating Tin
Net Weight 4.445/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 1/2" (M12)
Termination Interface: Style Crimp or Compression
Wire Size AWG 8

Material Info
Engineering Number D-352-12

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19193-036

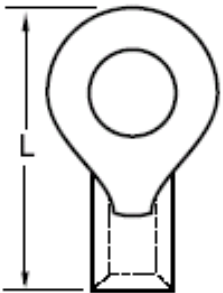

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -ED/01/2017 (12 January 2017)	
Halogen-Free Status	
Low-Halogen	
Need more information on product environmental compliance?	
Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19193](#) Series