


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5024940270](#)
Status: **Active**
Overview: CLIK-Mate Wire-to-Board Connectors
Description: 2.00mm Pitch CLIK-Mate Wire-to-Board PCB Receptacle, Single Row, Right-Angle, 2 Circuits

Documents:

| | |
|--|---|
| 3D Model (PDF) | Application Specification AS-502439-001-001 (PDF) |
| 3D Model | Application Specification AS-502439-002-001 (PDF) |
| Drawing (PDF) | Packaging Specification 5024949200-200 (PDF) |
| Product Specification 5024431570-000 (PDF) | RoHS Certificate of Compliance (PDF) |

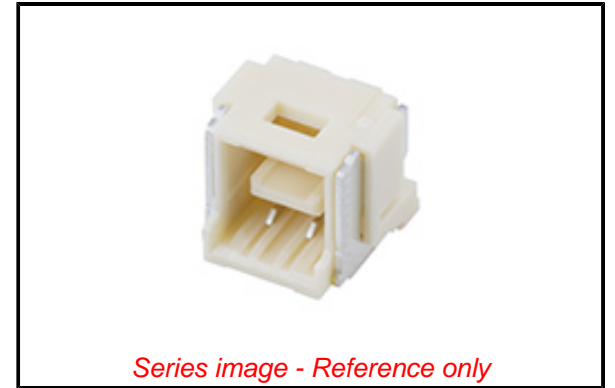

General

| | |
|----------------|--|
| Product Family | PCB Receptacles |
| Series | 502494 |
| Application | Signal, Wire-to-Board |
| Overview | CLIK-Mate Wire-to-Board Connectors |
| Product Name | CLIK-Mate |
| Taxonomy | PCB Headers and Receptacles |
| UPC | 822350936699 |

Physical

| | |
|--------------------------------|-----------------------|
| Circuits (Loaded) | 2 |
| Circuits (maximum) | 2 |
| Glow-Wire Capable | No |
| Guide to Mating Part | Yes |
| Keying to Mating Part | Yes |
| Lock to Mating Part | Yes |
| Mated Height | 6.90mm |
| Material - Plating Mating | Tin |
| Material - Plating Termination | Tin |
| Net Weight | 523.000/mg |
| Number of Rows | 1 |
| Orientation | Right Angle |
| PCB Locator | No |
| PCB Retention | Yes |
| Packaging Type | Embossed Tape on Reel |
| Pitch - Mating Interface | 2.00mm |
| Pitch - Termination Interface | 2.00mm |
| Plating min - Mating | 2.032µm |
| Plating min - Termination | 1.016µm |
| Polarized to Mating Part | Yes |
| Polarized to PCB | Yes |
| Stackable | No |
| Surface Mount Compatible (SMC) | Yes |
| Temperature Range - Operating | -40° to +105°C |
| Termination Interface: Style | Surface Mount |

Electrical

| | |
|-------------------------------|------------------|
| Current - Maximum per Contact | 3.0A |
| Voltage - Maximum | 250V AC (RMS)/DC |

Material Info

Reference - Drawing Numbers

| | |
|---------------------------|--------------------------------------|
| Application Specification | AS-502439-001-001, AS-502439-002-001 |
| Packaging Specification | 5024949200-200 |
| Product Specification | 5024431570-000 |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[502494](#) Series

Mates With

[502439](#) Crimp Housing

This document was generated on 10/26/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION