

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5051104091](#)
Status: **Active**
Overview: [Easy-On FFC FPC Connectors](#)
Description: Easy-On FFC/FPC Connector 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 40 Circuits, Gold over Nickel Plating

Documents:

3D Model (PDF)	Datasheet (PDF)
3D Model	Product Guide (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 5051100000-PS-000 (PDF)	Reference Guide (PDF)
Packaging Specification 5051109200-200 (PDF)	

General


Product Family	FFC/FPC Connectors
Series	505110
Comments	Black Actuator, Black Actuator
Datasheet Order No	987651-8731, 987651-8735_ZH, 987651-8767_DE, 987651-8771_JA, 987651-8775_KO, 987651-8779_ES
Overview	Easy-On FFC FPC Connectors
Product Guide Order No	987651-8061
Product Literature Order No	987652-0194, Reference Guide#
Product Name	Easy-On
Series Name	FD19
UPC	887191626321

Physical

Actuator Type	Flip
Circuits (Loaded)	40
Color - Resin	Beige
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	1.90mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold over Nickel
Material - Plating Termination	Gold over Nickel
Material - Resin	Liquid Crystal Polymer
Net Weight	324.100/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Pitch - Termination Interface	0.50mm
Plating min - Mating	0.051µm
Plating min - Termination	0.051µm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire/Cable Type	FFC/FPC

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V AC (RMS)/DC

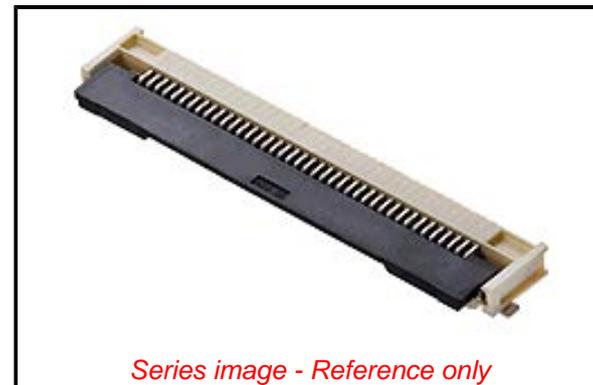

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[505110 Series](#)

Mates With

Premo-Flex FFC Cable [15020](#) , [15018](#)

Material Info

Reference - Drawing Numbers

Packaging Specification

5051109200-200

Product Specification

5051100000-PS-000

Sales Drawing

5051100000-SD-000, 5051101000-SD-000

This document was generated on 11/18/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION