


## 5748665 -2 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

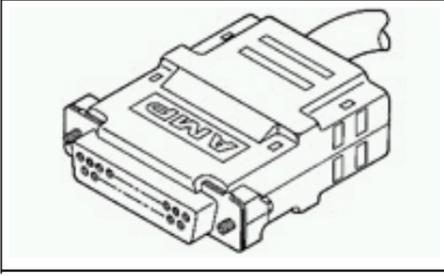

**5748665 -2**

[Active](#)

### Cable Clamps

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

#### Product Highlights:

- ? Backshell/Cable Clamp
- ? Cable Clamp Type = Clam Shell
- ? 180° Cable Exit Angle
- ? Cable Insulation Diameter = 4.83 - 13.46 mm
- ? Number of Positions = 25

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- ? [UNIVERSAL CABLE CLAMP KIT, SHIELDED, SIZE 3, 25 POSI...](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- ? None Available

#### Product Specifications:

- ? None Available

#### Application Specifications:

- ? None Available

#### Instruction Sheets:

- ? None Available

#### CAD Files:

- ? None Available

#### Additional Information:

- ? [Product Line Information](#)

#### Related Products:

- ? [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? [Product Type](#) = Backshell/Cable Clamp
- ? [Cable Clamp Type](#) = Clam Shell
- ? Number of Positions = 25
- ? [Shell Size](#) = 3
- ? [Shielded](#) = Yes
- ? [Grommets](#) = Without
- ? Thread Size = 4 -40

#### Body Related Features:

- ? [Cable Exit Angle](#) = 180°
- ? [Cable Insulation Diameter \(mm \[in\]\)](#) = 4.83 - 13.46 [0.190 - 0.530]
- ? Cable Clamp Material = ABS
- ? Shield Plating = Bright Nickel over Copper

#### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- ? [Packaging Method](#) = Bulk

#### Other:

- ? Brand = AMP