

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300240165**
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change Single-Ended Cordset, 5 Poles, Male (90°) to Pigtail, 16 and 20 AWG, DeviceNet Mid Cable, 5.0m (16.40') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
 Series 130024
 Connector End A Mini-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Brass
 Overview Brad® Mini-Change® Connectors
 Product Name DeviceNet* Trunk, Mini-Change®
 Region Europe
 Type Single Ended
 UPC 78678883498

Physical

Cable Diameter 8.38mm (.330")
 Cable Length 5.0m (16.40')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Male-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Die-Cast Zinc
 Material - Plating Mating Gold
 Orientation 90° to Pigtail
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 16, 20
 Wire/Cable Type Mid Cable

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DNB09A-M050

Reference - Drawing Numbers

Sales Drawing SD-130024-008

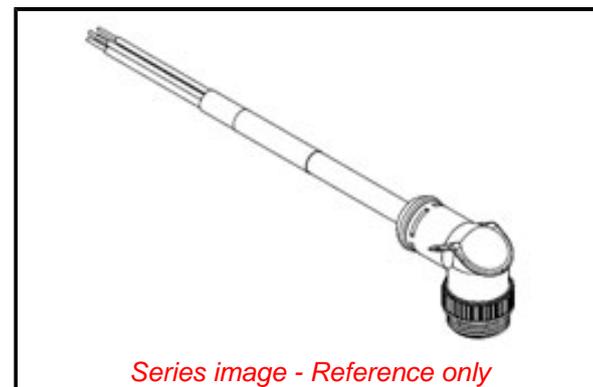

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130024 Series