

COIL:


RESISTANCE 700 Ω ± 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 1.5 VDC

CUSTOMER DATA SHEET

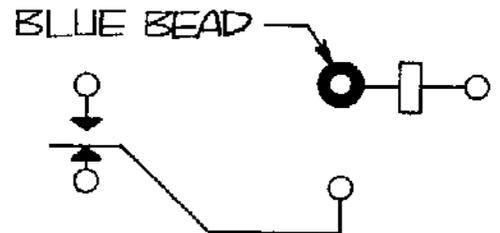

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 100 g's 5 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

CONTACT RATING: 10 AMP/28 VDC
RESISTIVE 50,000 OPERATIONS

NOTES: DIELECTRIC-1000 VRMS EXCEPT
500 VRMS ACROSS OPEN CONTACTS

DR. R. B. 1-30-91 OK. 1/30/91 JMB

Communications Instruments, Inc.

CUST. C.I.I. STD

CUST. NO. _____

TYPE "C" RELAY

CEW-1C-24A