

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200808005](#)
Status: **Active**
Overview: Brad Ultra-Lock Connection System
Description: Micro-Change (M12) to Ultra-Lock (M12) Double-Ended Cordset, 4 Poles, Male (Straight) to Female (Straight), 22 AWG, PUR Cable, 5.0m (16.40') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120080
Connector End A	Micro-Change (M12)
Connector End B	Ultra-Lock (M12)
IP Rating	IP69K
Material - Contact	Copper Alloy
Overview	Brad Ultra-Lock Connection System
Product Name	Micro-Change (M12), Ultra-Lock (M12)
Region	Europe
Type	Double Ended
UPC	883906398064

Physical

Cable Diameter	5.30mm (.209")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	22
Wire/Cable Type	EU Cable

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info

Engineering Number	8W4030P03M050
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-120080-006
---------------	---------------

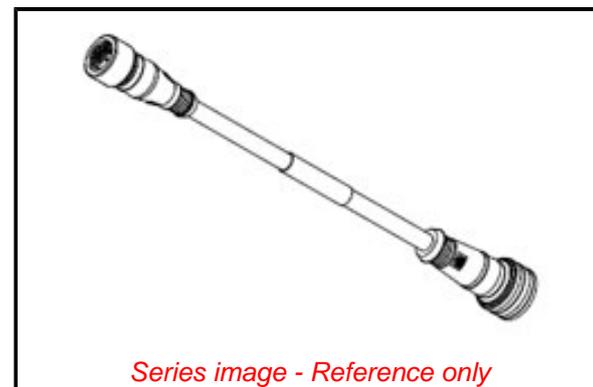

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[120080](#) Series

Mates With

[120341](#) Micro-Change CAT6A Receptacles