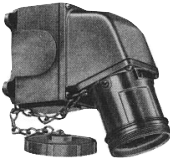


Russellstoll[®]

Heavy Service Ever-Lok[®] – Ordering Information

		Plugs	Connectors	Receptacles	
					
Configuration				HSF Series Basic Receptacle	HSA Series*
30 Amp	2P, 3W	8407	8443	HSF8403	8403
	3P, 4W	8408	8444	HSF8404	8404
60 Amp	2P, 3W	8417	8453	HSF8413	8413
	3P, 4W	8418†	8454	HSF8414	8414
100 Amp	3P, 4W	8428-72	8464-72	HSF8424-72	8424-72

Note:
Reverse service available by adding "R" suffix to catalog number. Solder lugs on 100 amp only.

Connectors – can be furnished with conduit adapters to accommodate rigid conduit or standard connectors for armored and non-metallic cable or flexible conduit. See page 93.

* Can be furnished with 45° angle adapter when specified on order. Add suffix -45 to catalog number.
Flap Covers are standard on all receptacles.

Std. Cable Bushing (see page 10 for other bushings)		
Current Rating	Bushing	Max. AWG Size
30	7/8"	#8, -7 strand or flexible
60	1 3/16"	#4, -7 strand or flexible
100	1 1/2"	#2, -7 strand or flexible

Conduit Size		
Current Rating	Std. Size	Max. Size
30	1"	1 1/4"
60	1"	1"
100	2"	2"

Cable Conduit Adapters: see page 93.

†Note: 9418/F27194 Automotive 480VAC Version

Outlet Location: Standard Series

