


+ TERMINALS & SPLICES

SPLICES

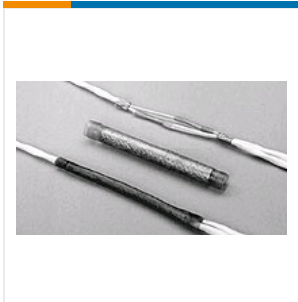

✓ Active

↓ PRODUCT DRAWING
English

TE CONNECTIVITY
D-150-0330

Raychem

CA3119-000

TE Internal Number: CA3119-000
 Alias ID: D-150-0330

Not reviewed for RoHS Compliance

Product Type **Splice**

Splice Type **SolderShield**

Wire/Cable Type **Multi-Conductor**

Product Drawings

[Shielded Cable Splice Kit Tin-Plated Shield And Crimp](#)
 PDF
English

Catalog Pages/Data Sheets

[1654025_Sec8_D-150](#)
 PDF
English

Product Specifications

Product Specification

[Installation Procedure For Raychem Shielded Cable Splice Kits With Mini-Seal Crimp Primary Splices](#)
 PDF
English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type	Splice
Splice Type	SolderShield
Wire/Cable Type	Multi-Conductor

Configuration Features

Number of Conductors	Two-conductor cable
----------------------	----------------------------

Body Features

Plating Material	Tin/Silver
------------------	-------------------

Usage Conditions

Operating Temperature (Max) (°C)	150
----------------------------------	------------

Product Compliance

[Statement of Compliance](#)
PDF

[VIEW ALL PRODUCT COMPLIANCE](#)