


HEAT SHRINK TUBING

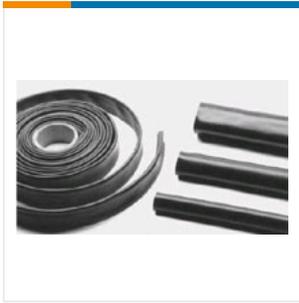

✓ Active

TE CONNECTIVITY
BSTS-11X25/CL

Raychem | BSTS

CB5024-000
 TE Internal Number: CB5024-000
 Alias ID: 3-1195009-9, BSTS-11X25/CL

Always EU RoHS/ELV Compliant

Wall Type **Single**

Resistant To **Abrasion, Fluids, Mechanical Damage, Strain**

Low Outgassing **No**

Product Source **US**

Packaging Method **Piece**

Catalog Pages/Data Sheets

[BSTS_BSTS-FR Pages From 9-1773447-9](#)
 PDF
 English

Product Specifications

Product Specification [Raychem BSTS/BSTS-FR Tubing General Purpose Polyolefin Heat-Shrinkable](#)
 PDF
 English

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features	Wall Type	Single
	Product Family	BSTS
Electrical Characteristics	Voltage (Max) (kV)	.6
Body Features	Shrink Ratio	3:1
	Color	Clear
	Flexibility	Semi-Rigid
	Material	Irradiated Modified Polyolefin
	Fluid Type	Water
Dimensions	Recovered Inside Diameter (Max)	9.52 mm [.375 in]
	Recovered Wall Thickness (Tolerance)	3.05 mm [.12 in]

Expanded Inside Diameter (Min) **27.94 mm [1.1 in]**

Cut Length (in) **300**

Usage Conditions	Resistant To	Abrasion, Fluids, Mechanical Damage, Strain
	Recovery Temperature (°C)	121
	Operating Temperature Range (°C)	-55 – 110
	Flammability	Non-Flame-Retardant
	Fluid Resistance	Immersion Protection, Splash Protection
	Shrink Temperature (Min) (°C)	90

Product Availability	Applicable Region	Global
----------------------	-------------------	---------------

Packaging Features	Packaging Method	Piece
--------------------	------------------	--------------

Other	Low Outgassing	No
	Product Source	US

Product Compliance	Statement of Compliance PDF
	VIEW ALL PRODUCT COMPLIANCE

No compatible products found for CB5024-000