


**+** IDENTIFICATION AND LABELING

## BLANK DIE-CUT LABELS

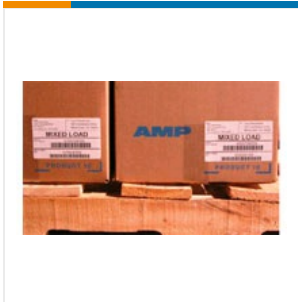

✓ Active

**TE CONNECTIVITY**  
**EP-508127-5-9**

EP

EP-508127-5-9

TE Internal Number: E61543-000  
 Alias ID: 1200605-5

Always EU RoHS/ELV Compliant

Label Type **Die-Cut**

Adhesive Type **Permanent Rubber-Based**

Label Width **50.8 mm [ 2 in ]**

Number of Labels Across **1**

Label Height **12.7 mm [.5 in ]**

No documentation available.

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features	Self-Laminating	<b>No</b>
	Product Type	<b>Labels</b>
	Tamper Evident	<b>No</b>
Configuration Features	Number of Labels Across	<b>1</b>
Body Features	Material	<b>Paper</b>
Usage Conditions	Operating Temperature Range	<b>-54 – 66 °C [ -65 – 150 °F ]</b>
Operation/Application	Recommended Ribbon	<b>1330-0600-10</b>
	Energy Product	<b>Yes</b>
	Recommended Printer	<b>T3085</b>
Printer/Label Features	Label Type	<b>Die-Cut</b>
	Adhesive Type	<b>Permanent Rubber-Based</b>
	Label Width	<b>50.8 mm [ 2 in ]</b>
	Label Height	<b>12.7 mm [.5 in ]</b>

Label Color	<b>White</b>
Web Width	<b>56.9 mm [ 2.24 in ]</b>
Vertical Repeat	<b>15.9 mm [.63 in ]</b>
Printer Type	<b>Thermal Transfer</b>

---

Identification Marking	Energy Label Type	<b>Pressure Sensitive</b>
	Performance Labels	<b>No</b>

---

Packaging Features	Packaging Quantity	<b>5000</b>
	Packaging Method	<b>Roll</b>

---

Product Compliance

[Statement of Compliance](#)  
PDF

[VIEW ALL PRODUCT COMPLIANCE](#)

No compatible products found for EP-508127-5-9