


HEAT SHRINK TUBING

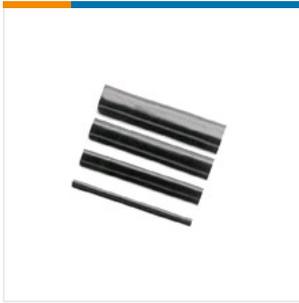

✓ Active

TE CONNECTIVITY

SST-48-07/RED/226/NM

Raychem | SST

CB5340-000

TE Internal Number: CB5340-000

Always EU RoHS/ELV Compliant

Wall Type **Single**

Resistant To **Abrasion, Fluids, Moisture**

Low Outgassing **No**

Product Source **US**

Packaging Method **Piece**

Catalog Pages/Data Sheets

[SST And SST-FR Pages From 9-1773447-9](#)

PDF
English

Product Specifications

Product Specification

[Raychem SST/SST-FR Tubing Adhesive Sealing Heat-Shrinkable](#)

PDF
English

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features	Wall Type	Single
Body Features	Shrink Ratio	3:1
	Color	Red
	Flexibility	Semi-Rigid
	Material	Irradiated Modified Polyolefin
	Fluid Type	De-Icing Fluid, Hydraulic Fluid, Lubricating Oil, Turbine Fuel
Dimensions	Recovered Inside Diameter (Max)	5.6 mm [.2204 in]
Usage Conditions	Resistant To	Abrasion, Fluids, Moisture
	Recovery Temperature (°C)	121
	Flammability	Non-Flame-Retardant

Fluid Resistance

Moisture/Spray Protection

Shrink Temperature (Min) (°C)

90

Product Availability

Applicable Region

Global

Packaging Features

Packaging Method

Piece

Other

Low Outgassing

No

Product Source

US

Product Compliance

[Statement of Compliance](#)
PDF

[VIEW ALL PRODUCT COMPLIANCE](#)

No compatible products found for CB5340-000