


HEAT SHRINK TUBING

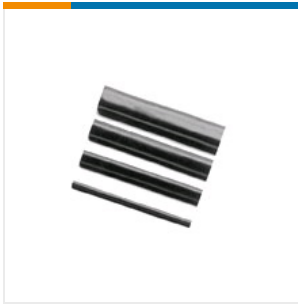

✓ Active

TE CONNECTIVITY

SST-12-04-RED/226

Raychem | SST

CB5271-000

TE Internal Number: CB5271-000

Always EU RoHS/ELV Compliant

Wall Type **Single**

Resistant To **Abrasion, Fluids, Moisture**

Low Outgassing **No**

Product Source **US**

Packaging Method **Piece**

Catalog Pages/Data Sheets

[SST And SST-FR Pages From 9-1773447-9](#)

PDF
English

Product Specifications

Product Specification

[Raychem SST/SST-FR Tubing Adhesive Sealing Heat-Shrinkable](#)

PDF
English

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features	Wall Type	Single
Body Features	Shrink Ratio	3:1
	Color	Red
	Flexibility	Semi-Rigid
	Material	Irradiated Modified Polyolefin
	Fluid Type	De-Icing Fluid, Hydraulic Fluid, Lubricating Oil, Turbine Fuel
Dimensions	Recovered Inside Diameter (Max)	3.81 mm [.15 in]
	Recovered Wall Thickness (Tolerance)	1.78 mm [.07 in]
	Expanded Inside Diameter (Min)	10.2 mm [.4 in]
	Cut Length	305 mm [12 in]

Usage Conditions	Resistant To	Abrasion, Fluids, Moisture
	Recovery Temperature (°C)	121
	Operating Temperature Range (°C)	-55 – 90
	Flammability	Non-Flame-Retardant
	Fluid Resistance	Moisture/Spray Protection
	Shrink Temperature (Min) (°C)	90

Product Availability	Applicable Region	Global
----------------------	-------------------	---------------

Packaging Features	Packaging Method	Piece
--------------------	------------------	--------------

Other	Low Outgassing	No
	Product Source	US

Product Compliance

[Statement of Compliance](#)
PDF

[VIEW ALL PRODUCT COMPLIANCE](#)