




# CRN-1/16-X-STK

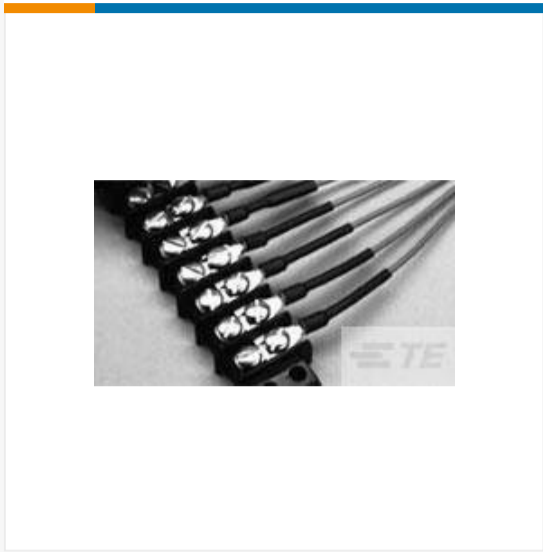

**! PENDING OBSOLESCENCE**

TE Part # **CRN-1/16-X-STK**  
TE Internal #: **5250022017**  
Mil-Spec: **M23053/6-202-C**  
Alias #: **1-1194124-8**

Color : **Clear**  
Wall Type : **Single**  
Expanded Inside Diameter (Min) : **1.6 mm**  
[ **.063 in** ]  
Recovered Inside Diameter (Max) : **.79 mm**  
[ **.031 in** ]  
Shrink Ratio : **2:1**

[Add to List](#) ▾

### We are here to help!

Get in touch with our product experts.

[CHAT WITH US](#)

[EMAIL US](#)

[CALL US](#)

## Replacement Parts

Replacement part information for TE Part #5250022017. **Replacement products may not be a form, fit and function replacement, nor an exact substitute for your application. Please use the Product Drawing to validate use in your application.**



TE Part #: **NB15242001**  
**CRN-1/16-X-STK**

[View Product](#)

### Features

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features	Wall Type : <b>Single</b> Product Family : <b>CRN</b>
Electrical Characteristics	Voltage (Max) (kV): <b>.6</b>
Body Features	Color : <b>Clear</b> Shrink Ratio : <b>2:1</b> Material : <b>Irradiated Modified Polyolefin</b> Flexibility : <b>Semi-Rigid</b> Fluid Type : <b>Aviation Fuel, Hydraulic Fluid, Water</b>

Dimensions	Expanded Inside Diameter (Min): <b>1.6 mm [ .063 in ]</b> Recovered Inside Diameter (Max): <b>.79 mm [ .031 in ]</b> Cut Length: <b>1220 mm [ 48 in ]</b> Recovered Wall Thickness (Tolerance): <b>.51 mm [ .02 in ]</b>
Usage Conditions	Shrink Temperature (Min) (°C): <b>110</b> Resistant To: <b>Abrasion, Fluids, Strain</b> Operating Temperature Range (°C): <b>-55 – 135</b> Flammability: <b>Non-Flame-Retardant</b> Recovery Temperature (°C): <b>135</b> Fluid Resistance: <b>Splash Protection</b>
Product Availability	Applicable Region: <b>Global</b>
Packaging Features	Packaging Method: <b>Stick</b>
Other	Product Source: <b>Czech Republic, US</b> Low Outgassing: <b>No</b>


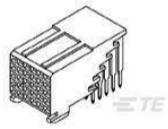
 
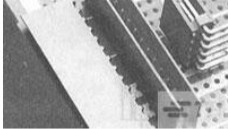
Feedback



Compatible Parts

> [Contact Product Support](#)

Customers Also Bought

 <p>TE Part # DK-602-0156-N-2 <b>DK-602-0156-N-2</b></p> <p><a href="#">View Product</a></p>	 <p>TE Part # 5223007-2 <b>FB-5R, ASY, 060, SIG, REC, SL, 3.53</b></p> <p><a href="#">View Product</a></p>	 <p>TE Part # 445159-1 <b>RECPT, LGH 1/4</b></p> <p><a href="#">View Product</a></p>	 <p>TE Part # 281696-2 <b>HEADER HE13 STRAIGHT 2 P</b></p> <p><a href="#">View Product</a></p>
---	---	---	---