


## 5352359-1 Product Details

Have a Question?

Chat with a Product Information Specialist

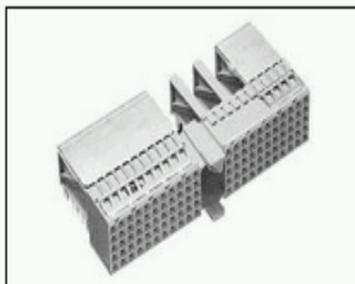

5352359-1

TE Internal Number: 5352359-1

Active

### 2mm Hard Metric PCB Mount Connectors (Z-PACK 2mm HM)

Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

**Product Highlights:**

- Connector
- Connector Assembly
- Connector Style = Receptacle
- Type = Type A
- Interface Type = 2mm HM

[View all Features](#)

**Quick Links**

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [View Mating Products \(1\)](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

**Documentation & Additional Information**

**Product Drawings:**

- [Z-PACK 2mm HM TYPE A - 16 COLUMNS \(J4 VERSION\) PRE-S...](#) (PDF, English)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- None Available

**Application Specifications:**

- None Available

**Instruction Sheets:**

- None Available

**CAD Files:**

- None Available

**Additional Information:**

- [Product Line Information](#)

**Related Products:**

- [Tooling](#)
- [Mating Products \(1\)](#)

[List all Documents](#)

**Product Features** (Please use the Product Drawing for all design activity)

**Product Type Features:**

- Product Type = Connector
- Connector Type = Connector Assembly
- [PCB Mount Angle](#) = Right Angle
- [Mating Polarization](#) = With
- [Mating Polarization Type](#) = Multi-Purpose Center
- Comment = Integrated Ground Return Upper shields.

**Mechanical Attachment:**

- [Board Mount](#) = Free Board
- [Module Length \(mm \[in\]\)](#) = 50.00 [1.968]
- [Crosstalk Version](#) = Standard
- Front Mating Level = Level 1

**Electrical Characteristics:**

- [Shielded](#) = Yes

**Termination Related Features:**

- [Interface Type](#) = 2mm HM
- Termination End Plating = Tin over Nickel

**Body Related Features:**

- [Type](#) = Type A
- [Number of Rows](#) = 5
- [Number of Positions](#) = 90
- [Grounding Contact](#) = Without
- Rows Loaded = A, B, C, E, D
- Number of Signal Contacts = 90
- CompactPCI Designation = J4 (Telephony)

**Contact Related Features:**

- [Contact Configuration](#) = Signal
- [Feedthrough Post Length \(mm \[in\]\)](#) = 3.30 [0.130]
- [CompactPCI](#) = Yes
- [Contact Plating, Mating Area, Material](#) = Gold (30)
- Contact Style = Feed through
- Contact Base Material = Phosphor Bronze

**Housing Related Features:**

- Connector Style = Receptacle
- Housing Material = Polyester GF
- Housing Color = Gray
- UL Flammability Rating = UL 94V-0

**Industry Standards:**

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

**Other:**

- Brand = AMP

BOOKMARK

**Corporate Information**

- [Who We Are](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)

**Quick Links**

- [Check Distributor Inventory](#)
- [Cross Reference](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

**Customer Support**

- [Email or Chat with Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

**Sign up for our eNewsletter**

Enter your email address

**Follow Us On:**



**Visit Us On:**

