



My Cart |

My Part Lists | Sign In/Register

English (Change)



What can we help you find?




- Products
- Industries
- Resources
- About TE
- Support Center
- My Account

Home > Products > Identification Products > Product Feature Selector > Product Details

### CC9135-000 Product Details

[Share](#) [Print](#) [Email](#)

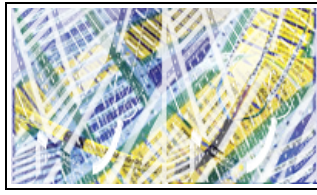

#### CC9135-000

(TMS-90-SCE-1F8-9)

TE Internal Number: CC9135-000

Active

#### Heat Shrink Sleeve

Always EU RoHS/ELV Compliant (Statement of Compliance)

#### Product Highlights:

- TMS-90-SCE Series
- Military Grade
- Radiation Cross-Linked Polyolefin Material
- Shrink Ratio = 2:1
- Operating Temperature = -55 - 135 °C

[View all Features](#)

#### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

#### Documentation & Additional Information

##### Product Drawings:

- None Available

##### Catalog Pages/Data Sheets:

- None Available

##### Product Specifications:

- None Available

##### Application Specifications:

- None Available

##### Instruction Sheets:

- None Available

##### CAD Files:

- None Available

##### Related Products:

- [Tooling](#)

#### Product Features (Please use the Product Drawing for all design activity)

##### Product Type Features:

- Series = TMS-90-SCE
- Grade = Military
- Material = Radiation Cross-Linked Polyolefin
- Color = White

##### Electrical Characteristics:

- Expanded ID, Min. (mm [in]) = 3.18 [0.125]
- Recovered ID, Max. (mm [in]) = 1.07 [0.042]

##### Body Features:

- Shrink Ratio = 2:1
- Recommended Wire OD Use Range (mm [in]) = 1.11 - 2.66 [0.044 - 0.105]
- Wall Thickness - Full Recovery (Nominal) (mm [in]) = 0.51 [0.020]

##### Industry Standards:

- RoHS/ELV Compliance = RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

##### Environmental:

- Operating Temperature (°C [°F]) = -55 - +135 [-67 - +275]

##### Packaging Features:

- Packaging Quantity = 5,000

##### Other:

- Brand = Raychem

#### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)

#### Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

#### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

#### Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

