


Board to Board Connectors 0.5 / 0.8mm FS (Fine-Stack) B to B Connectors


0.8mm Pitch Tab Assembly, With Key Housing

Material and finish :

Housing— glassfiber reinforced 6T nylon (heat resistant), beige
 Contact— 0.2mm thick phosphor bronze, tin-lead plated or gold plated over nickel underplate (See table)
 Tail plate— 0.2mm thick phosphor bronze, tin-lead plated or tin plated

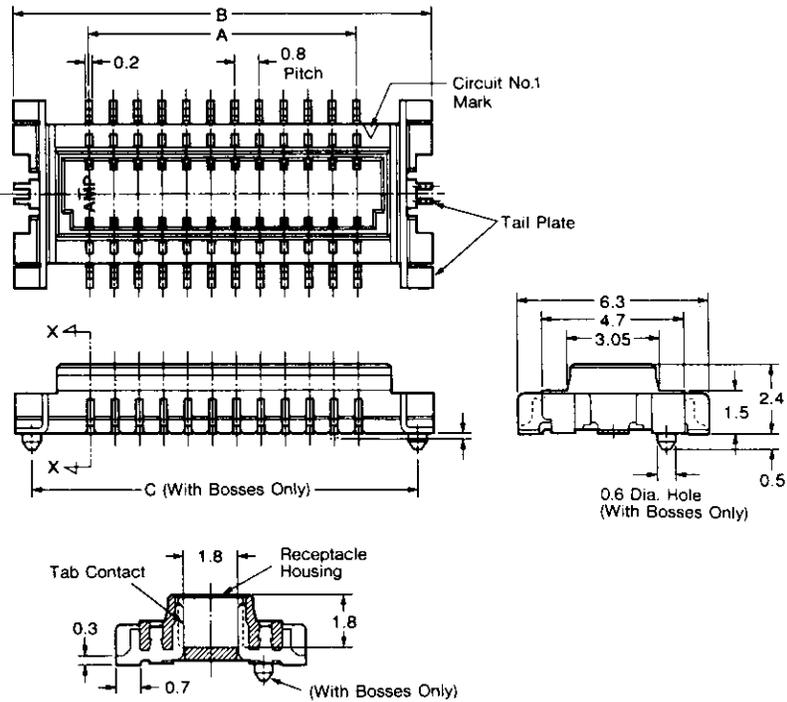

Section X-X

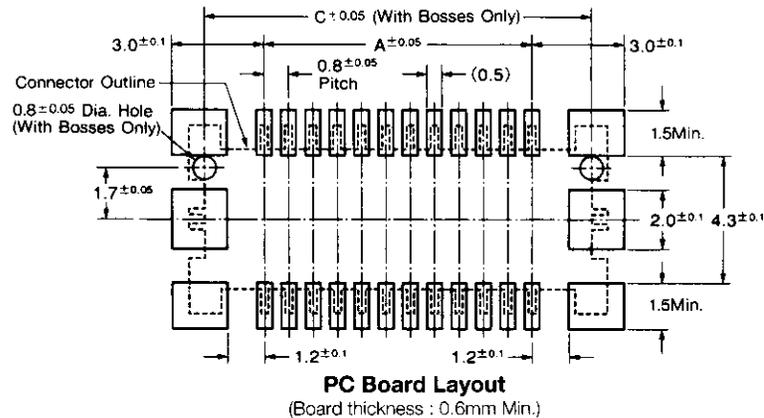

| No. of Pos. | Dimensions | | | Part Number of Tab Assembly (Tape Mounted) | | Width of Tape |
|-------------|------------|------|------|--|--------------|---------------|
| | A | B | C | With Boss | Without Boss | |
| 14 | 4.8 | 9.8 | 8.8 | 1-179397-4 | 1-179403-4 | 16 |
| | | | | 1-179703-4* | 1-179704-4* | |
| 16 | 5.6 | 10.6 | 9.6 | 1-179397-6 | 1-179403-6 | 16 |
| | | | | 1-179703-6* | 1-179704-6* | |
| 24 | 8.8 | 13.8 | 12.8 | 2-179397-4 | 2-179403-4 | 24 |
| | | | | 2-179703-4* | 2-179704-4* | |
| 30 | 11.2 | 16.2 | 15.2 | 3-179397-0 | 3-179403-0 | 24 |
| | | | | 3-179703-0* | 3-179704-0* | |
| 40 | 15.2 | 20.2 | 19.2 | 4-179397-0 | 4-179403-4 | 32 |
| | | | | 4-179703-0* | 4-179704-4* | |
| 50 | 19.2 | 24.2 | 23.2 | 5-179397-0 | — | 44 |
| | | | | 5-179703-0* | | |

Note : On each tape is loaded 1,500 assemblies.

*Gold plated over nickel underplate.