


## J4 Type A Right-Angle Female Connector (Computer Telephony)

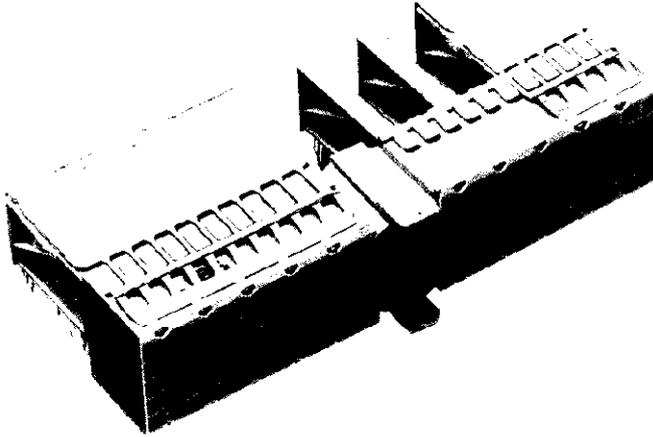

### Materials and Finish

Glass filled polyester housing, gray, UL 94 V-0 rated.  
 Phosphor-bronze signal contacts and shields  
 Contact area 0.8µm Au over 1.3µm Ni  
 ACTION PIN contact 0.5µm Sn/Pb over 1.3 µm Ni.

CompactPCI specified coding keys are available for this connector as shown on page 44.

Enhanced electrical performance is attained through the use of segmented pre-attached upper ground return shields.

The AMP proprietary "Chiclet" design provides for optimum high voltage isolation as specified in the Enterprise Computer Telephony Forum specification H.110 and the PICMG Computer Telephony specification.

- 90 signal contacts
- Length 49.9mm
- Daughter Card application

Technical documents see pg 82.

Connector Type	CompactPCI Designation	Number of Signal Contacts	Part Number
A (Select Load)	.4 (Telephony)	90	352359-1

