

**Vertical Female Connectors, 5 Row, Types A, B, and C**



**Vertical Female Connectors**

Types A, B and C mate with respective right angle and vertical male connectors shown on pages 211 and 220.

Type A has 110 contacts and center keying and guiding. Type B has 125 contacts and Type C has 55 contacts with guiding feature. All are stackable without change in contact pitch according to the chart on page 210.

Limited other contact patterns are available; see page 243.

**Electrical Characteristics** — page 208


**Materials and Finish**

Glass filled polyester housing.  
Phosphor-bronze signal contacts  
Contact area 0.8µm Au over 1.3µm Ni  
ACTION PIN contact 0.5µm Sn/Pb over 1.3 µm Ni.

**Coding keys for type A** page 243.

**Board layout** page 258 for guidance only.

**Tooling** — page 354.

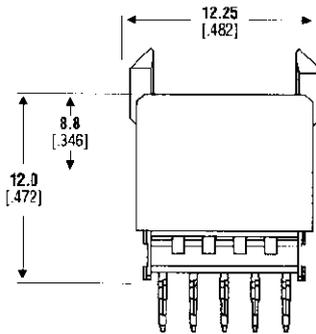

3.3 [130]

Type A shown

**Part Numbers**

Type A (without locating peg)	106773-1
Type A (with locating peg)	352457-1
Type B	106774-1
Type B 22 col	352258-1
Type B 19 col	352259-1
Type C	106775-1

